




Dimensions

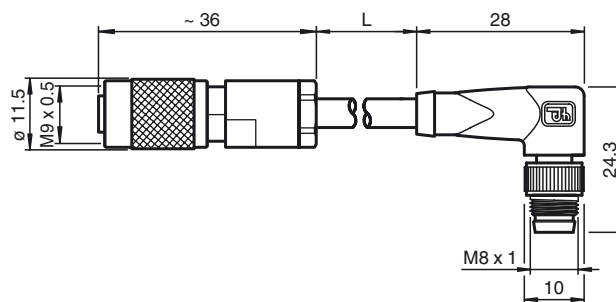

Model Number

V35-G-4M-PUR-V31-WM
 Connection cable, M9 to M8, PUR cable, 3-pin

Features

- Metal housing
- EMC shielded
- Screw lock
- Gold-plated and machined contacts
- Halogen-free

Technical data

General specifications

Number of pins	3
----------------	---

Electrical specifications

Operating voltage	U_B	max. 30 V DC
Test voltage		> 1500 V _{eff} AC
Operating current	I_B	max. 3 A
Volume resistance		< 5 mΩ

Ambient conditions

Ambient temperature	-25 ... 85 °C (-13 ... 185 °F)
---------------------	--------------------------------

Mechanical specifications

Contact elements	spring-loaded contact socket
Pin diameter	1 mm
Degree of protection	IP67


Material

Contacts	CuSn / Au
Contact surface	Au
Body	PA 66, black TPU, green

Cable

Cable	PUR
Slotted nut	CuZn, nickel-plated
Sleeve connector	Diecast zinc
Core insulation	PP
Cable	fine-strand, flexible
Sheath diameter	Ø4.8 mm
Bending radius	> 10 x cable diameter, moving
Color	grey
Cores	3 x 0.34 mm ²
Conductor construction	19 x 0.15 mm Ø
Length	L 4 m

Electrical connection

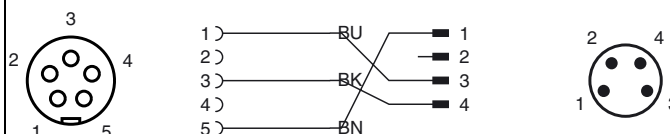

Release date: 2017-02-14 08:34 Date of issue: 2017-02-14 208135_eng.xml

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".