

# Inductive sensor


## NBB0,8-5GM25-E2-0,3M-V3



- Basic series
- 0.8 mm flush
- Cable with M8 plug



### Dimensions

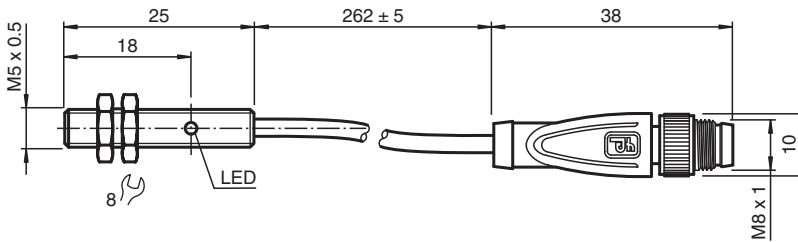

### Technical Data

#### General specifications

Switching function		Normally open (NO)
Output type		PNP
Rated operating distance	$s_n$	0.8 mm
Installation		flush
Output polarity		DC
Assured operating distance	$s_a$	0 ... 0.648 mm
Reduction factor $r_{Al}$		0.45
Reduction factor $r_{Cu}$		0.4
Reduction factor $r_{304}$		0.77
Output type		3-wire

#### Nominal ratings

Operating voltage	$U_B$	10 ... 30 V
Switching frequency	$f$	0 ... 3000 Hz
Hysteresis	$H$	typ. 5%
Reverse polarity protection		reverse polarity protected
Short-circuit protection		pulsing
Voltage drop	$U_d$	$\leq 3$ V
Operating current	$I_L$	0 ... 200 mA
Off-state current	$I_r$	0 ... 0.1 mA typ. 0.1 $\mu$ A at 25 °C
No-load supply current	$I_0$	$\leq 10$ mA
Switching state indicator		LED, yellow

#### Compliance with standards and directives

Release date: 2024-04-25 Date of issue: 2024-04-25 Filename: 224136\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com

USA: +1 330 486 0001  
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111  
fa-info@de.pepperl-fuchs.com

 
Singapore: +65 6779 9091  
fa-info@sg.pepperl-fuchs.com

**PF** PEPPERL+FUCHS

## Technical Data

Standard conformity		
Standards	EN IEC 60947-5-2	
<b>Approvals and certificates</b>		
UL approval	cULus Listed, General Purpose	
CCC approval	CCC approval / marking not required for products rated ≤36 V	
<b>Ambient conditions</b>		
Ambient temperature	-25 ... 70 °C (-13 ... 158 °F)	
<b>Mechanical specifications</b>		
Connection type	fixed cable with plug	
Housing material	Stainless steel 1.4305 / AISI 303	
Sensing face	PC	
Degree of protection	IP67	
Connector		
Threading	M8 x 1	
Number of pins	3	
Cable		
Cable diameter	3 mm - 0.2 mm	
Bending radius	> 12 x cable diameter	
Material	PVC	
Color	grey	
Number of cores	3	
Core cross section	0.14 mm <sup>2</sup>	
Length	L	0.3 m
Dimensions		
Length	25 mm	
Diameter	5 mm	

## Connection



## Connection Assignment



Wire colors in accordance with EN 60947-5-2

1	BN	(brown)
3	BU	(blue)
4	BK	(black)