




## Connection cable V19-G-BK5M-PVC-U-V19-G

- Degree of protection IP67 / IP68 / IP69
- Oil resistant
- cURus approval
- Knurled nut suitable for tool assembly
- Immunity to vibration, with mechanical latching

Cordset M12 socket straight to M12 plug straight A-coded, 8-pin, PVC cable black, UL approved



### Dimensions

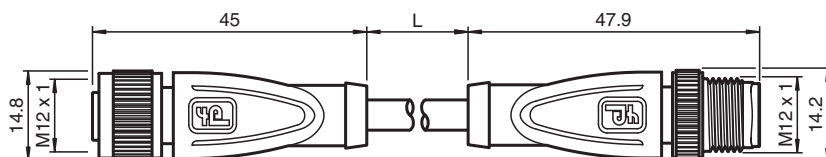

### Technical Data

#### General specifications

<b>Connector 1</b>			
Connection		socket	
Construction type		M12	
Style		straight	
Locking		screw connection	
Number of pins		8	
Coding		A-coded	
<b>Connector 2</b>			
Connection		plug	
Construction type		M12	
Style		straight	
Locking		screw connection	
Number of pins		8	
Coding		A-coded	
UL File Number		E231213	

#### Electrical specifications

Operating voltage	$U_B$	max. 30 V AC/DC	
Operating current	$I_B$	max. 2 A	

#### Conformity

Degree of protection		EN 60529	
Plug connection		connector M12 x 1 : IEC 61076-2-101	
Flammability		UL 758 / 1581 , IEC 60332-1-2	
Oil resistance		DIN EN 60811-2-1	

Release date: 2023-07-03 Date of issue: 2023-07-04 Filename: 240775-100086\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com

USA: +1 330 486 0001  
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111  
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091  
fa-info@sg.pepperl-fuchs.com

PEPPERL+FUCHS

**Technical Data**

**Approvals and certificates**

UL approval	AWM STYLE 2464 AWM I A/B 80°C 300V FT1 (cable)
-------------	--

**Ambient conditions**

Ambient temperature	
Plug connector	-40 ... 90 °C (-40 ... 194 °F)
Cable, fixed	-40 ... 80 °C (-40 ... 176 °F)
Cable, flexing	-20 ... 80 °C (-4 ... 176 °F)
Pollution degree	3




**Mechanical specifications**

Plug connector	
Tightening torque	0.6 Nm
Loosening protection	available
Tool installation	straight knurling
Mating cycles	min. 100
Degree of protection	IP67 / IP68 / IP69
Cable	
Sheath diameter	6.3 mm
Bending radius	> 10 x cable diameter, moving > 5 x cable diameter, fixed
Sheath stripping force	max. 50 N / 300 mm
Sheath color	black (similar to RAL 9005)
Number of cores	8
Core cross section	0.34 mm <sup>2</sup>
Cores color	Core 1: white Core 2: brown Core 3: green Core 4: yellow Core 5: grey Core 6: pink Core 7: blue Core 8: red
Core construction	42 x 0.1 mm Ø
Length	L 5 m
Cable code	Li Y YM 8 x 0,34

**Material**

Plug connector	
Screw connection	Zinc diecast, nickel-plated
Body	TPU, black
Contact surface	Au
Flammability	V-2
Cable	
Sheathing	PVC
Core insulation	PVC
Oil resistance	yes
Flammability	FT1

**Connection**

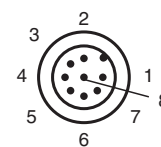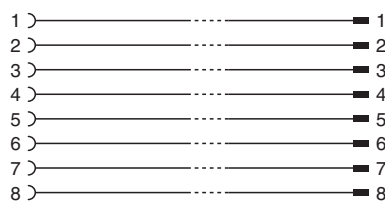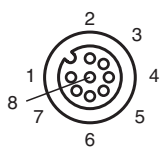

Release date: 2023-07-03 Date of issue: 2023-07-04 Filename: 240775-100086\_eng.pdf

**Accessories**

	<b>MH V1-SCREWDRIVER</b>	Torque screwdriver (0.6 Nm)
	<b>MH V1-BIT M12</b>	plug-in cap M12
	<b>V1/V3-LABELHOLDER</b>	Label holder
	<b>V1/V3-LABEL</b>	Label plate
	<b>MH V1-Holder</b>	Modular universal holder for M12 connectors
	<b>V1-CLIP</b>	Unlocking protector for M12 connector
	<b>V1-MARKING-RING-COLOR</b>	Marking rings for M12 connectors, various colors

Release date: 2023-07-03 Date of issue: 2023-07-04 Filename: 240775-100086\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com

USA: +1 330 486 0001  
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111  
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091  
fa-info@sg.pepperl-fuchs.com