



Model Number


V1-G-YE2M-PUR-H/S

Female cordset, M12, 4-pin, irradiated PUR cable

Features

- Knurled nut suitable for tool assembly
- Immunity to vibration, with mechanical latching
- Gold-plated and machined contacts
- Degree of protection IP68 / IP69K
- Suitable for 2-, 3- and 4-wire technology

Dimensions

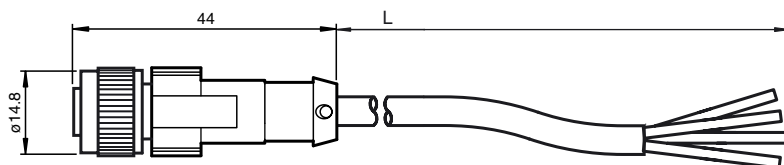

Technical data

General specifications

Number of pins	4
----------------	---

Electrical specifications

Operating voltage	U_B	max. 300 V DC
Test voltage		> 1500 V _{eff} AC
Operating current	I_B	max. 4 A
Volume resistance		< 5 mΩ


Ambient conditions

Ambient temperature	-40 ... 80 °C (-40 ... 176 °F)
Pollution degree	3

Mechanical specifications

Contact elements	spring-loaded contact socket
Pin diameter	1 mm
Degree of protection	IP68 / IP69K
Material	
Contacts	CuSn / Au
Contact surface	Au
Body	TPU, yellow
Cable	PUR, irradiated
Slotted nut	Diecast zinc
Core insulation	polyester
Cable	fine-strand, flexible
Sheath diameter	Ø 6.2 mm
Color	yellow
Cores	4 x 0.75 mm ²
Conductor construction	24 x 0.2 mm
Length	L 2 m

Electrical connection

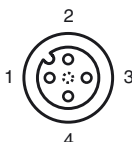

1	BN
2	WH
3	BU
4	BK