


Female cordset ML29 Kupplungsdose 6m 4polig

- Special snap-in connector for ML29 series

Female cordset with 6 m cable for ML29 series sensors

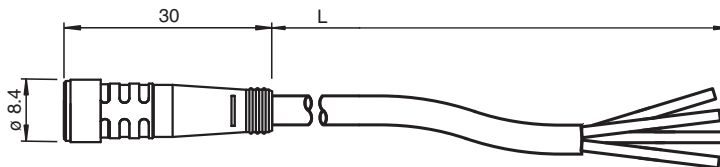

Technical Data

| General specifications | | | |
|---------------------------|-------|---|---|
| Number of pins | | | 4 |
| Connection 1 | | socket | |
| Construction type 1 | | straight | |
| Threading 1 | | M8 | |
| Connection 2 | | cable end | |
| Electrical specifications | | | |
| Operating voltage | U_B | max. ... 30 V | |
| Operating current | I_B | max. 4 A | |
| Ambient conditions | | | |
| Ambient temperature | | -30 ... 90 °C (-22 ... 194 °F) | |
| Pollution degree | | 3 | |
| Mechanical specifications | | | |
| Degree of protection | | IP67 according to EN 60529 (when properly seated) | |
| Material | | | |
| Body | | TPU, blue | |
| Cable | | PVC | |
| Cable | | | |
| Sheath diameter | | Ø 3.5 mm | |

Release date: 2024-03-26 Date of issue: 2024-03-26 Filename: 131595_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

 PEPPERL+FUCHS

Technical Data

| | | |
|--------|------|--------------------------|
| Color | grey | |
| Cores | | 4 x 0.14 mm ² |
| Length | L | 6 m |

Connection Assignment

