



### Model Number


#### ML29 Kupplungsdose 3m 4polig

Female cordset with 3 m cable for ML29 series sensors

### Features

- Special snap-in connector for ML29 series

### Dimensions

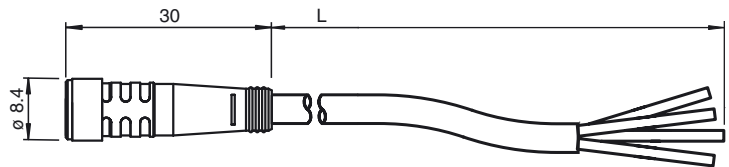

### Technical data

#### General specifications

Number of pins	4
Connection 1	socket
Construction type 1	straight
Threading 1	M8
Connection 2	cable end

#### Electrical specifications

Operating voltage	$U_B$	max. ... 30 V
Operating current		max. 4 A

#### Ambient conditions

Ambient temperature	-30 ... 90 °C (-22 ... 194 °F)
Pollution Degree	3

#### Mechanical specifications

Degree of protection	IP67 according to EN 60529 (when properly seated)
Material	
Body	TPU, blue
Cable	PVC
Cable	
Sheath diameter	Ø 3.5 mm
Color	grey
Cores	4 x 0.14 mm <sup>2</sup>
Length	L 3 m

### Electrical connection



1	-----	BN
2	-----	WH
3	-----	BU
4	-----	BK