




DoorScan® door transition cable DoorScan Transfer Loop



- Door transition cable to connect the sensor to the controller
- Connection to interface module

Door transition cable to door controller for DoorScan® sensor, including cable sheathing and strain relief

Dimensions

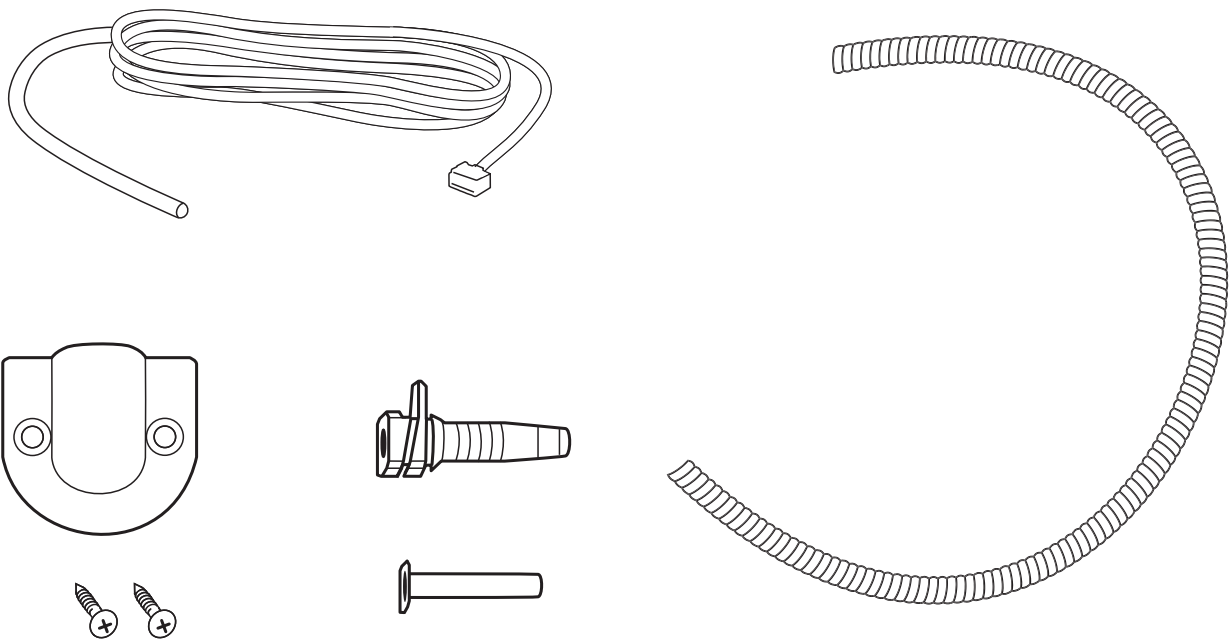

Technical Data

Electrical specifications

Operating voltage U_B max. 300 V

Ambient conditions

Ambient temperature -25 ... 80 °C (-13 ... 176 °F)

Mechanical specifications

Release date: 2020-09-10 Date of issue: 2020-10-08 Filename: 247291_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

PF PEPPERL+FUCHS

Technical Data

Connection	screw terminal , 6-pin	
Material	Cable sheathing: polyamide PA 6, black , Wall bracket: ABS	
Cable	PUR, gray, 6-wire	
Sheath diameter	approx. 4.8 mm	
Bending radius	min. 48 mm	
Length	L	5000 mm
Mass	approx. 110 g	
General information		
Scope of delivery	Wall bracket , Screw kit , cord grip , cable , Cable sheathing , Hollow rivet	
Suitable series		
Series	DoorScan®	

Mounting

Wall mount bracket

