

Bestellbezeichnung / Model Number

VBA-4E3A-G20-ZEL/E2L-P5

VBA-4E3A-G20-ZEL/E2L-P11



Zulassungen und Zertifikate / Approvals and certificates

UL-Zulassung / UL approval


cULus Listed, Type 1 enclosure

UL File Number







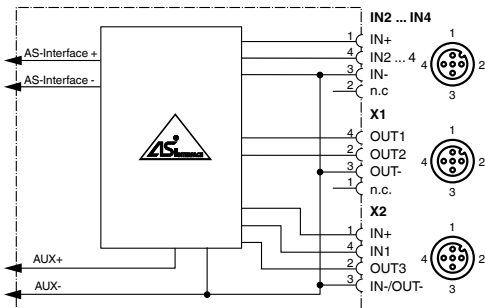

E223772



„For use in NFPA 79 Applications only“

Elektrischer Anschluss / Electrical connection



UL-anerkannte Flachkabel von P+F / UL recognized flat cable from P+F

Bestell- bezeichnung Order code	Farbe Color	Material	Aderquerschnitt Cross-section	UL cable style	Zulassungen Approvals
VAZ-FK-R-YE	gelb/ yellow	TPE	2 x 1.5 mm ²	2103	CE  
VAZ-FK-R-BK	schwarz/ black	TPE	2 x 1.5 mm ²	2103	CE  
VAZ-FK-PUR-YE	gelb/ yellow	PUR	2 x 1.5 mm ²	20549	CE  
VAZ-FK-PUR-BK	schwarz/ black	PUR	2 x 1.5 mm ²	20549	CE  

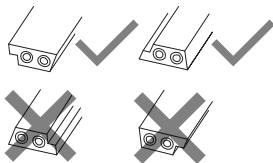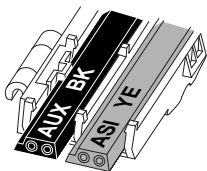

Anschluss gem. IEC/EN 61076-2-101 / Connection acc. to IEC/EN 61076-2-101

Ein- Ausgänge Inputs/Outputs	M12, 4-polig, Buchsenkontakte, Schraubverriegelung, A-kodiert M12, 4-pin, bushing contacts, screw lock, A-coded
Gegenstecker Mat. connector	M12, 4-polig, Steckerkontakte, Schraubverriegelung, A-kodiert M12, 4-pin, male contacts, screw lock, A-coded