

Bestellbezeichnung / Model Number

VAA-4E2A-G1-ZE/PEXT-S
VAA-4E2A-G1-ZE/P-S
VBA-4E2A-G1-ZE/PEXT-S
VBA-4E2A-G1-ZE/P-S



Elektrische Daten / Electrical specification



Bemessungsbetriebsspannung $U_e \leq 32$ V PELV
Rated operating voltage $U_e \leq 32$ V PELV

Bemessungsbetriebsstrom $I_e \leq 45$ mA (ohne Sensoren)
Rated operating current $I_e \leq 200$ mA (gesamt)

Umgebungsbedingungen / Ambient conditions

Umgebungstemperatur / Ambient temperature 0 ... 55 °C / 32 ... 131 °F


Lagertemperatur / Storage temperature -20 ... 85 °C / -4 ... 185 °F

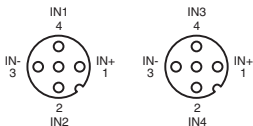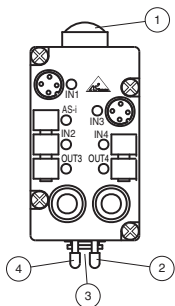


- 1 Abluft / Outgoing air
- 2 Handbetätigung / Manual operation
- 3 Luftzufuhr / Air supply
- 4 Handbetätigung / Manual operation

Beispiele für Funktionen der Airbox Examples for functions of the Airbox

3/2-Wege-Ventil / 3/2-way valve

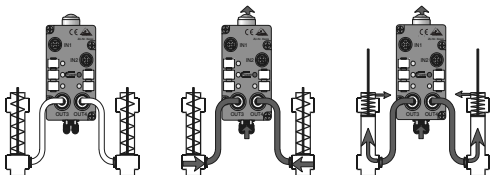

4/2-Wege-Ventil / 4/2-way valve

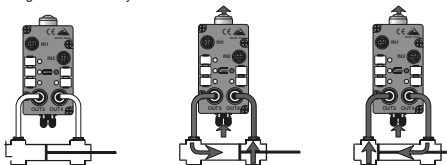

5/2-Wege-Ventil / 5/2-way valve

