

Bestellbezeichnung / Model Number

ICA-16IO-G20-IO-P16*

ICA-8I8IO-G20-IO-P15*



Zulassungen und Zertifikate / Approvals and certificates

UL-Zulassung / UL approval

cULus Listed, Type 1 enclosure


UL File Number

E223772


„For use in NFPA 79 Applications only“

Elektrischer Anschluss / Electrical connection

ICA-16IO-G20-IO-P16*

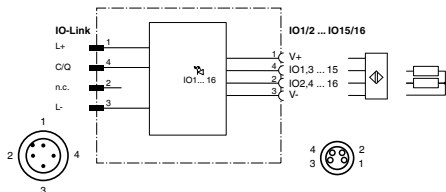

ICA-8I8IO-G20-IO-P15*

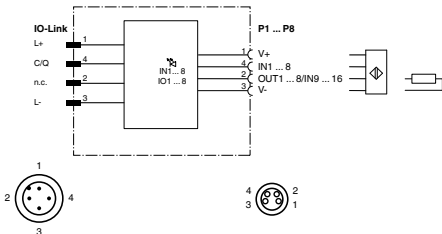

Anschluss gem. IEC/EN 61076-2-101 / -104
Connection acc. to IEC/EN 61076-2-101 / -104

IO-Link M12-Rundsteckverbinder, Style LM
(4-polig, Steckerkontakte, Schraubverriegelung, A-kodiert)
M12 connector, Style LM
(4-pin, connector contacts, screw locking, A-coded)

Ein- Ausgänge M8-Rundsteckverbinder / M8 round plug connector
Inputs/Outputs

IO / P Style LF
(4-polig, Buchsenkontakte, Schraubverriegelung, A-kodiert)
(4-pin, female contacts, screw locking, A-coded)

Gegenstecker IO-Link: Style LF oder vergleichbar / or similar
Mat. connector IO / P: Style LM oder vergleichbar / or similar