


- DE** Sicherheitsschaltung
- EN** Fail-safe mode
- FR** Mode de sécurité
- ES** Modo de seguridad
- IT** Modalità di sicurezza
- NL** Veiligheidsschakeling

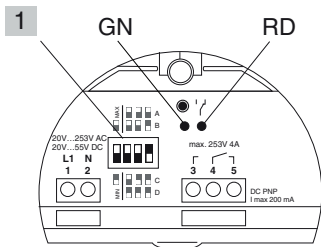

1		GN	RD	U <sub>DC</sub>	U <sub>AC/DC</sub>
				PNP	Relais
MAX 1 					
MIN 					

* $\epsilon_r$	g/l (min.)			
> 1.5	200			
> 1.7	250			
> 2.0	400			
> 3.0	800			
Getreide Grain Céréales Grano Graan				
* $\epsilon_r$	g/l (min.)			
> 1.5	500			
> 1.7	700			
> 2.0	1100			
Mineralien, Kunststoffe Minerals, Plastics Minéraux, Plastiques				
* $\epsilon_r$	g/l (min.)			
> 1.5	500			
> 1.7	700			
> 2.0	1100			
Minerales, plásticos Minerali, plastiche Mineralen, Kunststoffen				
* $\epsilon_r$	g/l (min.)			
> 1.5	500			
> 1.7	700			
> 2.0	1100			
Mineralien, Kunststoffe Minerals, Plastics Minéraux, Plastiques				

**DE** Funktionsoptimierung

**EN** Optimising Performance

**FR** Optimisation de fonction

**ES** Optimización del funcionamiento

**IT** Ottimizzazione delle prestazioni

**NL** Functieoptimalisatie

B = Werkeinstellung

B = Factory settings

B = Réglages usine

B = Ajustes de fábrica

B = Impostazione di fabbrica

B = Fabriekinstelling



71312101

KA00156O/98/A6/13.15  
DOCT-0581A 113720 01/2016

**PEPPERL+FUCHS**