
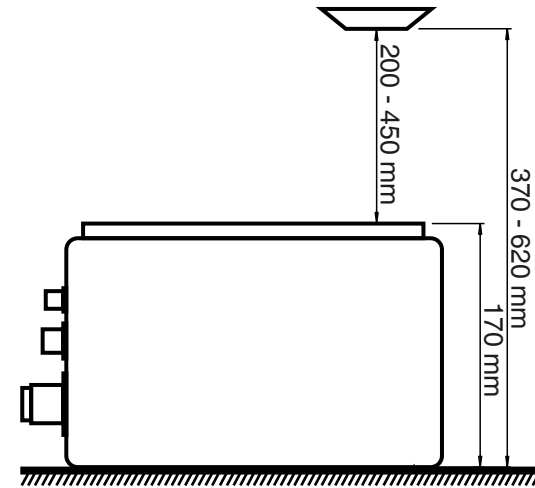


Permissible displacement of read-only tag ($\pm\Delta X$ and $\pm\Delta Y$) depending on reading distance Z


Default setting: $Z_w = 380$ mm
 Depth of focus at Z_w : $DoF = \pm 50$ mm

The values ΔX and ΔY apply for read-only tags OIC-C10V2A-CB1 and OIC-C10ST-CB1

Reading window in X and Y direction

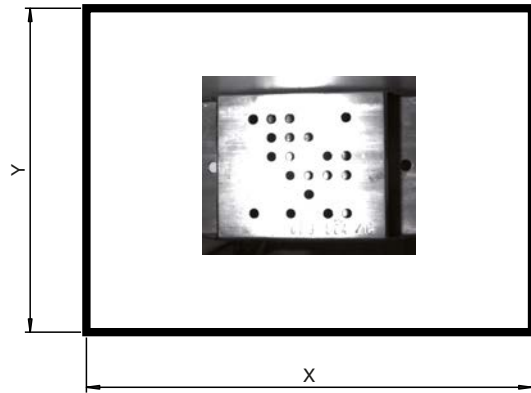


Depth of focus (DoF) = ± 50 mm
Zw = 380 mm

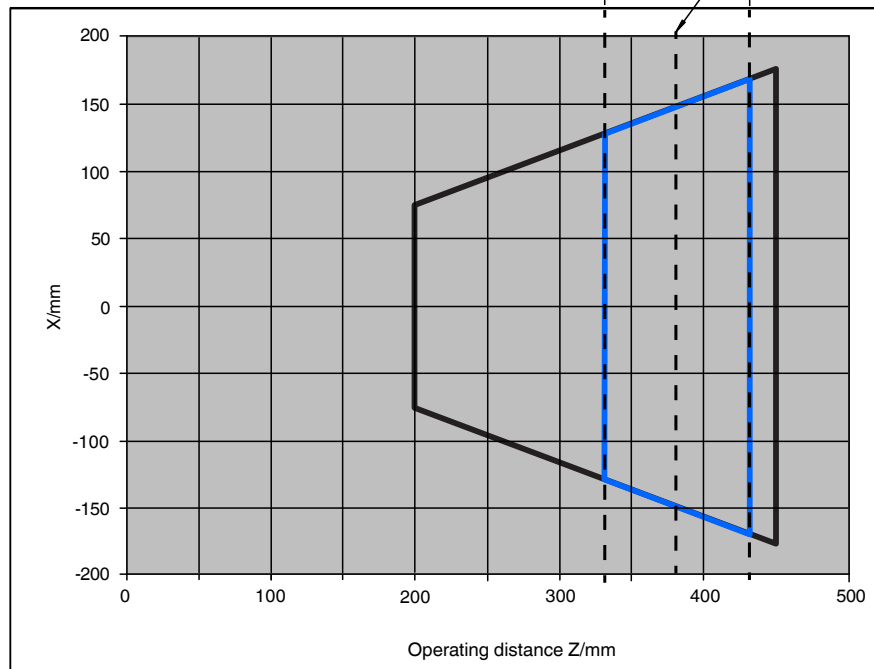

Reading window in X direction

Depth of focus (DoF) = ± 50 mm
Zw = 380 mm

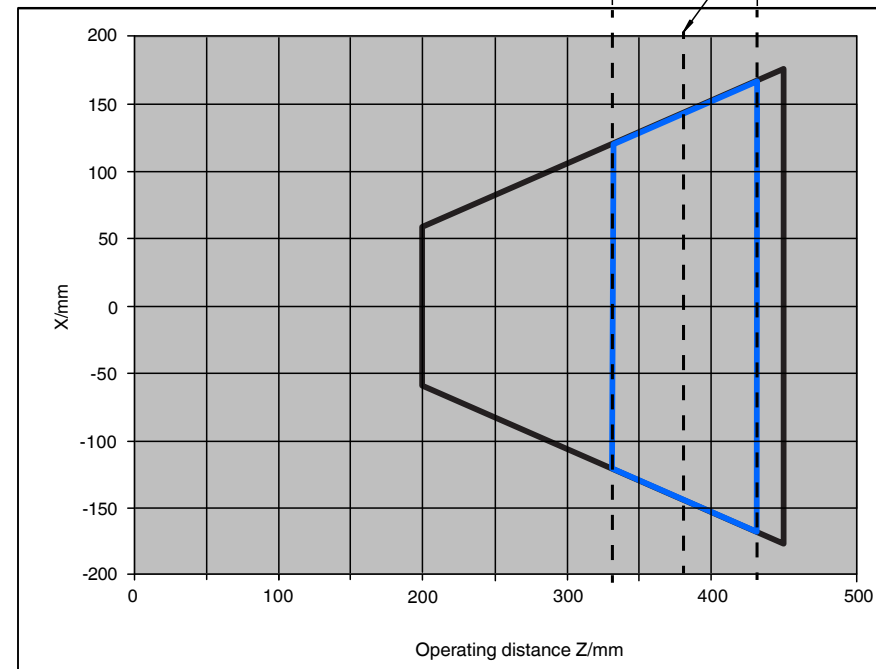

Reading window in Y direction