



CE


Model Number

NCB10-30GM60-Z0


Features

- Comfort series
- 10 mm embeddable

 Connection



Dimensions

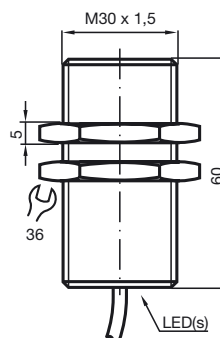

Technical Data

General specifications

Switching element function	DC	Make function
Rated operating distance	s_n	10 mm
Installation	embeddable	
Output polarity	DC	
Assured operating distance	s_a	0 ... 8.1 mm
Reduction factor r_{Al}	0.32	
Reduction factor r_{Cu}	0.32	
Reduction factor r_{V2A}	0.72	

Nominal ratings

Operating voltage	U_B	5 ... 60 V
Switching frequency	f	0 ... 70 Hz
Hysteresis	H	1 ... 15 typ. 5 %
Reverse polarity protection	tolerant	
Short-circuit protection	pulsing	
Voltage drop	U_d	≤ 5 V
Operating current	I_L	2 ... 100 mA
Off-state current	I_r	0 ... 0.9 mA typ. 0.7 mA
Indication of the switching state	LED, yellow	
Pre-fault indication	LED, red	

Standard conformity

Standards	IEC / EN 60947-5-2:2004
-----------	-------------------------

Ambient conditions

Ambient temperature	-25 ... 70 °C (248 ... 343 K)
Storage temperature	-40 ... 100 °C (233 ... 373 K)

Mechanical specifications

Connection type	2 m, PUR cable
Core cross-section	0.34 mm ²
Housing material	Stainless steel
Sensing face	PBT
Protection degree	IP67
Note	discontinued model