

Counter


KCM-70-C



- Electromechanical summator
- 7 decade devices
- Counter frequency 10 Hz
- Without reset
- Power supply 24 V DC
- Fixing with latching spring or latch fastener for easy installation
- Degree of protection IP42 in accordance with DIN EN 60529 (front only)
- Shock resistance in accordance with DIN EN 60068-2-27
- Vibration resistance in accordance with DIN EN 60068-2-6



Dimensions

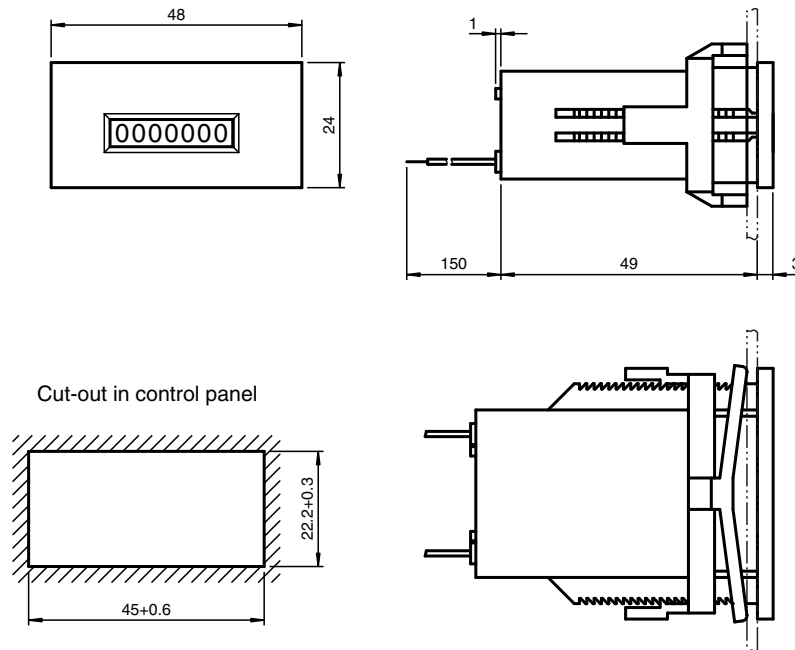

Technical Data

Indicators/operating means

Type	digital display
Number of digits	7
Display value	digit height 4 mm

Electrical specifications

Operating voltage	U_B	24 V DC
Power consumption	P_0	0.6 W

Input

Pulse length/pulse interval	50 ms / 50 ms
Counting frequency	10 Hz

Release date: 2023-11-21 Date of issue: 2023-11-21 Filename: 097902_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Technical Data

Ambient conditions

Ambient temperature	-10 ... 50 °C (14 ... 122 °F)
Storage temperature	-40 ... 90 °C (-40 ... 194 °F)
Relative humidity	≤ 80 % (noncondensing)

Mechanical specifications

Connection	flexible leads AWG 22 150 mm long
Mass	60 g
Dimensions	48 mm x 24 mm x 54 mm
Mounting	latch fastener
Life span	> 50 x 10 ⁶ pulses

Connection

