




Dimensions

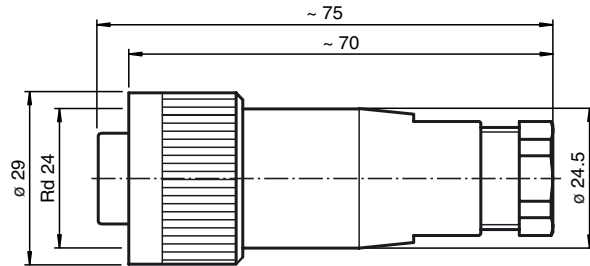

Model number

V16-G

Cable socket, dia. 24, 6-pin+PE, easy to assemble

Features

- Gold plated contacts

Technical data

General specifications

Number of poles	6 + PE
Connection 1	Connector, female
Construction type 1	straight
Threading 1	Rd 24

Electrical specifications

Operating voltage	max. 250 V
Operating current	max. 10 A

Ambient conditions

Ambient temperature	-40 ... 100 °C (233 ... 373 K)
Degree of soiling	3

Mechanical specifications

Protection degree	IP67
Connection	1 x socket, dia. 24 x 1/8" screw terminal for max. 1.5 mm ² PG9 screwed connection
Material	
Contacts	CuSn / Au
Handle	PBT
Cable	
Sheath diameter	6 ... 8 mm
Lifetime	> 500 plugging operations

Electrical connection

