




Dimensions

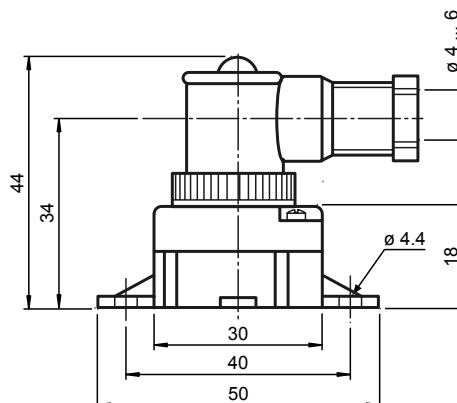

Model number

VAZ-T1-FK-W-PG7

Splitter box, AS-interface to M12 round connector, ready for assembly

Features

- Screw mounting for simple installation

Technical data

Electrical specifications

Rated operating voltage	U_e	26.5 ... 31.6 V
Rated operating current	I_e	≤ 2 A

Ambient conditions

Ambient temperature	-20 ... 70 °C (-4 ... 158 °F)
Pollution Degree	3

Mechanical specifications

Protection degree	IP67
Connection	AS-Interface flat cable
Material	
Contacts	CuZn
Contact surface	Au
Housing	PA
Cable	
Sheath diameter	4 ... 6 mm

Compliance with standards and directives

Standard conformity	
Protection degree	EN 60529:2000