




Dimensions

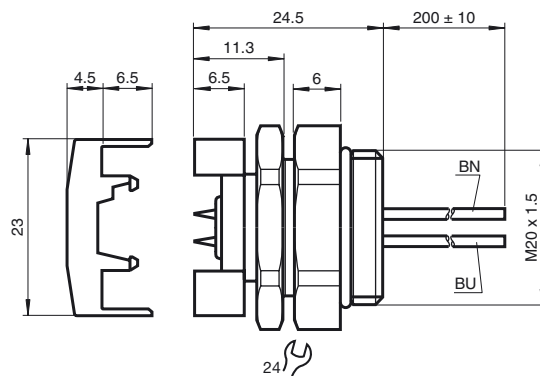

Model number

VAZ-T1-FK-M20

Screw adapter M20 x 1.5 with metal housing

Features

- Metal housing
- AS-Interface cable can be mounted in any position

Technical data

Ambient conditions

Ambient temperature	-25 ... 60 °C (-13 ... 140 °F)
Storage temperature	-25 ... 85 °C (-13 ... 185 °F)

Mechanical specifications

Protection degree	IP65 according to EN 60529
Connection	AS-Interface flat cable
Cable	
Cores	2 x 0.25 mm ²
Length	L Lead length approx. 200 mm