


Female cordset ML29 Kupplungsdose 3m 4polig

- Special snap-in connector for ML29 series

Female cordset with 3 m cable for ML29 series sensors

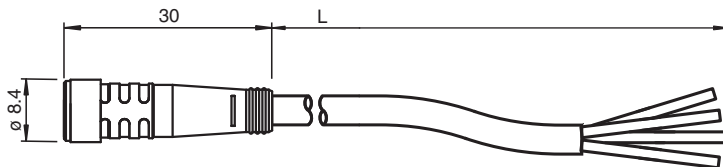

Technical Data

General specifications			
Number of pins			4
Connection 1			socket
Construction type 1			straight
Threading 1			M8
Connection 2			cable end
Electrical specifications			
Operating voltage	U_B	max. ...	30 V
Operating current	I_B	max.	4 A
Ambient conditions			
Ambient temperature			-30 ... 90 °C (-22 ... 194 °F)
Pollution degree			3
Mechanical specifications			
Degree of protection			IP67 according to EN 60529 (when properly seated)
Material			
Body			TPU, blue
Cable			PVC
Cable			
Sheath diameter			Ø 3.5 mm

Release date: 2024-03-26 Date of issue: 2024-03-26 Filename: 131596_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

 PEPPERL+FUCHS

Technical Data

Color	grey	
Cores		4 x 0.14 mm ²
Length	L	3 m

Connection Assignment



- 1 ————— BN
- 2 ————— WH
- 3 ————— BU
- 4 ————— BK

Release date: 2024-03-26 Date of issue: 2024-03-26 Filename: 131596_eng.pdf