




Dimensions

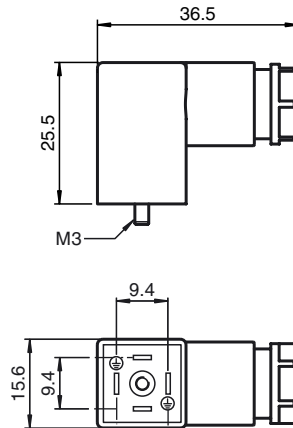

Model Number

VMCI-2+PE

Valve connector Form C (Ind), non pre-wired

Features

- Freely selectable cable outlet due to rotating insert

Technical data

General specifications

Number of poles	2 + PE
Connection 1	Valve connector industrial version
Construction type 1	angled

Electrical specifications

Operating voltage	U_B	250 V AC/DC
Operating current		max. 6 A
Volume resistance		< 15 m Ω

Ambient conditions

Ambient temperature	-20 ... 120 °C (253 ... 393 K)
Pollution Degree	3

Mechanical specifications

Protection degree	IP65
Connection	Valve connector shape C (Ind) Screw terminals for max. 0.75 mm ²
Material	
Contacts	CuSn
Contact surface	Ni
Handle	PA
Cable	
Sheath diameter	4 ... 6 mm

Electrical connection

