




**Model number**

**VAZ-PK-FK-0,2M-V1-W**

Adapter cable G10 module/hand-held programming device

**Electrical connection**

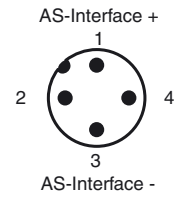

**Technical data**

<b>Ambient conditions</b>	
Ambient temperature	-25 ... 85 °C (-13 ... 185 °F)
<b>Mechanical specifications</b>	
Core cross-section	Copper tin-plated, extra-fine wire, class 6 in accordance with DIN VDE 0295 cross-section 1.5 mm <sup>2</sup>
Protection degree	IP20
Connection	AS-Interface flat cable: cable piercing method Connector: M12 x 1 (V1)
<b>Cable</b>	
Color	yellow (Similar to RAL 1012)
Mass	38 g
<b>Compliance with standards and directives</b>	
Standard conformity	
Protection degree	EN 60529:2000

**Notes**

**Handling:**  
 Connect the cable with the AS-Interface handheld via the M12-plug.  
 Insert the flat cable with the mark into the G10 module.  
 Change the address or parameters using our handheld.

Release date: 2010-06-02 08:10 Date of issue: 2014-01-13 225854\_eng.xml