


Inductive sensor


NBB1-5GM30-E0-0,5M-Y248061

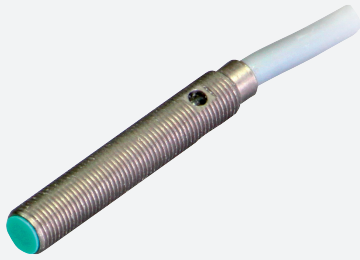

- Basic series
- 1 mm flush



Dimensions

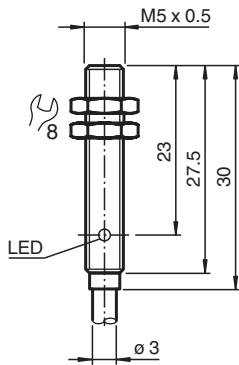

Technical Data

General specifications

Switching function	Normally open (NO)	
Output type	NPN	
Rated operating distance	s_n	1 mm
Installation	flush	
Output polarity	DC	
Assured operating distance	s_a	0 ... 0.81 mm
Reduction factor r_{Al}	0.4	
Reduction factor r_{Cu}	0.35	
Reduction factor r_{304}	0.78	
Reduction factor r_{Brass}	0.52	
Output type	3-wire	

Nominal ratings

Operating voltage	U_B	10 ... 30 V
Switching frequency	f	0 ... 3000 Hz
Hysteresis	H	1 ... 15 %
Reverse polarity protection	reverse polarity protected	
Short-circuit protection	pulsing	
Voltage drop	U_d	≤ 3 V
Operating current	I_L	0 ... 200 mA

Release date: 2024-04-25 Date of issue: 2024-04-25 Filename: 248061_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com


Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

 **PEPPERL+FUCHS**

Technical Data

Off-state current	I _r	0 ... 0.1 mA typ. 0.1 µA at 25 °C
No-load supply current	I ₀	≤ 10 mA
Switching state indicator		LED, red
Compliance with standards and directives		
Standard conformity		
Standards		EN IEC 60947-5-2
Approvals and certificates		
CCC approval		CCC approval / marking not required for products rated ≤36 V
Ambient conditions		
Ambient temperature		-25 ... 70 °C (-13 ... 158 °F)
Mechanical specifications		
Connection type		cable
Housing material		Stainless steel 1.4305 / AISI 303
Sensing face		POM
Degree of protection		IP67
Cable		
Wire end ferrules		yes
Cable diameter		3 mm - 0.2 mm
Bending radius		> 12 x cable diameter
Material		PVC
Color		grey
Number of cores		3
Core cross section		0.14 mm²
Length	L	0.5 m
Dimensions		
Length		30 mm
Diameter		5 mm

Connection

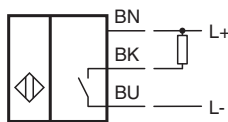

Release date: 2024-04-25 Date of issue: 2024-04-25 Filename: 248061_eng.pdf