 


Insert for DIN Mounting Rail

UPR-INS-05




- 5-conductor insert in 35 mm DIN mounting rail
- Suitable for 35 mm DIN mounting rail UPR-MR
- Suitable for profile rail K-DUCT
- Standard length 2 m (6 foot), simple to customize to application space


Function

The insert consists of plastic and has integrated gold-plated conductors. The insert is installed into the DIN mounting rail UPR-MR. The component has two conductors for power, one conductor for collective error messaging, and two conductors for bus connections. The component comes in 2 m segments but can be cut to any size. The DIN mounting rail UPR-MR and the insert UPR-INS-** form the Power Rail.

Assembly

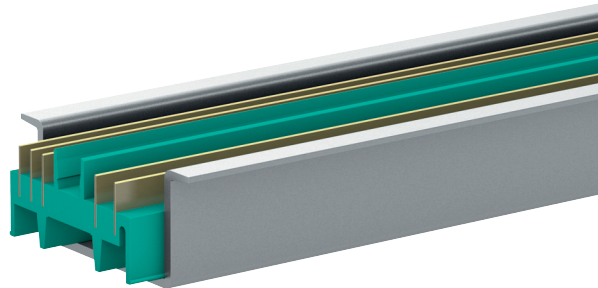

Dimensions

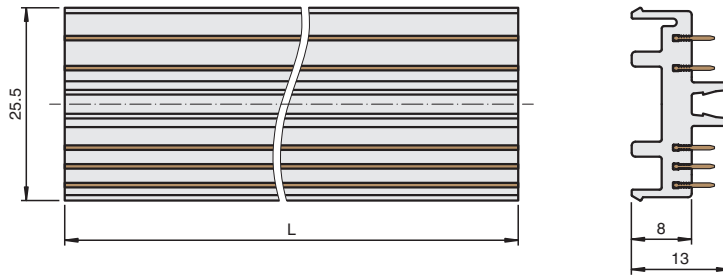

Technical Data

Mechanical specifications	
Connection	5 conductors
Supply	2 Conductors
Fault output	1 Conductors
Bus	2 Conductors
Material	Polycarbonate
Mass	approx. 500 g
Dimensions	13 x 25.5 x 2000 mm (0.5 x 1 x 78.7 inch)
Mounting	in 35 mm DIN mounting rail acc. to EN 60715:2001 Height: 15 mm
Accessories	
Designation	- DIN mounting rail UPR-MR - end cap UPR-E - cover UPR-COVER

Release date: 2020-09-23 Date of issue: 2020-09-23 Filename: 258159_eng.pdf