

Distributor


VAZ-CHAIN-BU/BN70MM/1,0-25

- For signal connection in control cabinets
- Using the multi-purpose twist-on connectors, the daisy chain can be adjusted to the required length and installed in the field
- Conveniently replace, install or remove individual modules without disrupting wiring

25-point wiring link for control cabinet modules with screw terminals



Dimensions

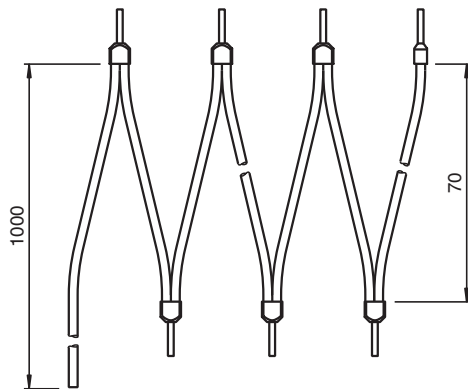

Technical Data

General specifications	
UL File Number	E223176
Electrical specifications	
Nominal voltage	48 V
Current loading capacity	8 A at 40 °C DIN VDE 0298 Part 4 HD 516/VDE 0298-300
Ambient conditions	
Ambient temperature	-30 ... 80 °C (-22 ... 176 °F) fixed
Mechanical specifications	
Core cross section	Fine-stranded copper 1 mm ²
Bending radius	Moving: 4 x external diameter Fixed: 2 x external diameter
Material	
Core insulation	PVC
Cable	H05V-K, rated voltage 300/500 V
Color	brown, blue
Connection possibilities	Suitable for screw terminals

Release date: 2022-06-30 Date of issue: 2022-06-30 Filename: 293151_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

PF PEPPERL+FUCHS

Technical Data

Cable length	25 x 7 cm + 1 m
Flammability	
Cable	Flame-retardant as per IEC 60332-1-2

Release date: 2022-06-30 Date of issue: 2022-06-30 Filename: 293151_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.comUSA: +1 330 486 0001
fa-info@us.pepperl-fuchs.comGermany: +49 621 776 1111
fa-info@de.pepperl-fuchs.comSingapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com **PEPPERL+FUCHS**