




Model Number

V19S-G-1,7/3M-PVC-V50

Adapter cable, M12 8-pin to RS 232

Dimensions

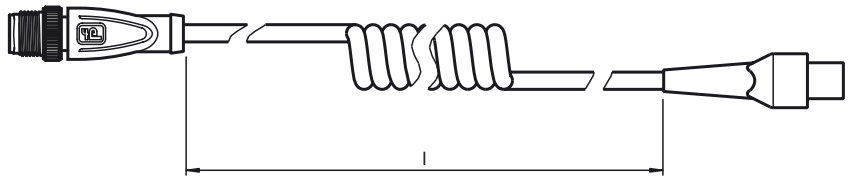

Technical data

Electrical specifications

Operating voltage U_B max. 30 V AC/DC

Input

Input voltage 5 V DC

Input current min. 500 mA

Mechanical specifications

Connection M12 connector, 8-pin
RJ-50, 10-pin

Cable

Color black

Number of cores 6

Core cross-section 0.14 mm^2

Shield grid

Length L Coiled Cable: 1.7 m / 3,3 m stretched

Mass approx. 170 g

Electrical connection

