



Model Number


V15S-G-0,5M-CGR-AB

Adapter cable for programmable ENI58PL-*****-1024CGR-*AB

Features

- Cordset for IO-Link USB master to programmable rotary encoders

Dimensions

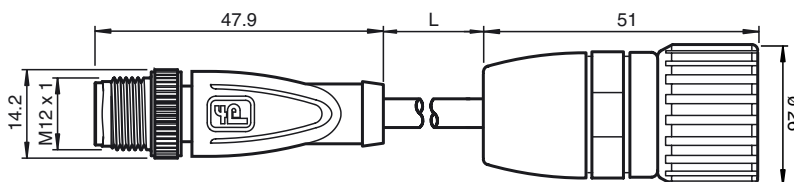

Technical data

General specifications

Number of pins	5/12 Left-rotating
Connection 1	Male connector
Construction type 1	straight
Threading 1	M12
Connection 2	socket
Construction type 2	straight
Threading 2	M23

Electrical specifications

Operating voltage	U_B	max. 30 V DC
Operating current	I_B	max. 500 mA at 24 V DC


Ambient conditions

Ambient temperature	-5 ... 70 °C (23 ... 158 °F)
---------------------	------------------------------

Mechanical specifications

Contact elements	spring-loaded contact socket
Degree of protection	IP44
Material	
Body	TPU, black
Cable	PVC
Cable	fine-strand, flexible
Sheath diameter	Ø 4.6 mm
Bending radius	≥ 69 mm, movable ≥ 27.6 mm, fixed
Color	grey
Length	L 0.5 m

Electrical connection

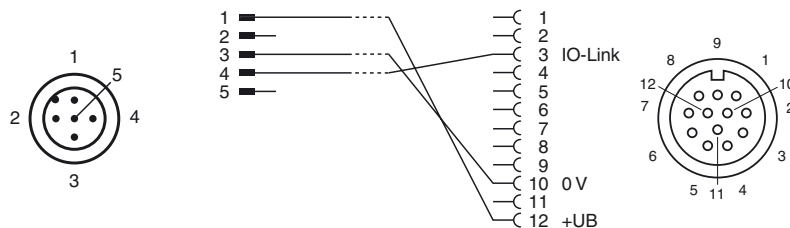

Release date: 2019-05-28 14:33 Date of issue: 2019-05-28 305763_eng.xml

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".