


# Locknuts

## LN.M40.BN.K25

- Brass nickel-plated
- Thread M40
- Packaging unit: 25 pieces

### Dimensions

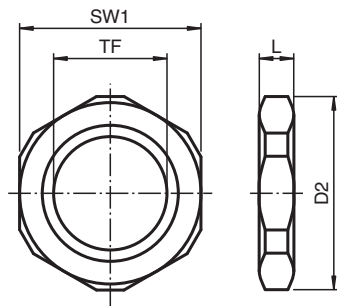

Dimension values see data table.  
Image and drawing are generic for this component type and may deviate from the specific variant.

Legend	
D2	Width across corners
L	Total length
SW1	Width across flats
TF	Thread size female

### Technical Data

Mechanical specifications	
Thread type	metric ISO pitch 1.5 mm
Thread size female (TF)	M40
Material	brass, nickel-plated
Finish	inherent color silver
Dimensions	
Width across corners (D2)	51 mm

Release date: 2020-06-02 Date of issue: 2020-06-02 Filename: 312479\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com

USA: +1 330 486 0002  
pa-info@us.pepperl-fuchs.com

Germany: +49 621 776 2222  
pa-info@de.pepperl-fuchs.com
















Singapore: +65 6779 9091  
pa-info@sg.pepperl-fuchs.com

**PF** PEPPERL+FUCHS

## Technical Data

Width across flats (SW1)	46 mm
Total length (L)	5 mm
<b>General information</b>	
Delivery quantity	25
Scope of delivery	Locknuts

## Matching system components

	<b>CG.AR.M40.SS.C.16.K10</b>
	<b>CG.AR.M40.BN.C.16.K05</b>
	<b>CG.CO.M40.BN.C.18.K05</b>
	<b>CG.EM.M40.BN.C.20.K05</b>
	<b>CG.EM.M40.SS.C.20.K05</b>
	<b>CG.NA.M40S.BN. C.18.K05</b>
	<b>CG.NA.M40S.SS. C.18.K05</b>
	<b>AD.M40.M32.BN. C.18.K20</b>
	<b>AD.M40.NPT1-1/2.BN. C.18.K20</b>
	<b>AD.M40.NPT1-1/2.SS. C.18.K20</b>
	<b>AD.M40.NPT1-1/4.BN. C.18.K20</b>
	<b>AD.M40.NPT1-1/4.SS. C.18.K20</b>
	<b>SP.MD.M40.BN.C.17.K10</b>
	<b>SP.MD.M40.SS.C.17.K10</b>
	<b>SP.PE.M40.PA.C.18.K10</b>

Release date: 2020-06-02 Date of issue: 2020-06-02 Filename: 312479\_eng.pdf