




# washer gasket

## WA.FL.M20.F.K100

- For thread M20
- Packaging unit: 100 pieces

### Dimensions

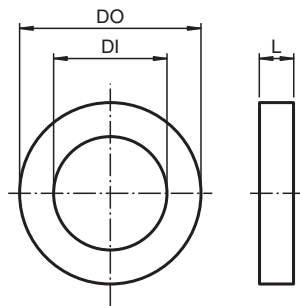

Dimension values see data table.  
Image and drawing are generic for this component type and may deviate from the specific variant.

Legend	
DO	Outer diameter
DI	Inside diameter
L	Total length

### Technical Data

#### Mechanical specifications

Material	aramid fibers bonded with NBR
Finish	inherent color green
Dimensions	
Outer diameter (DO)	23.8 mm
Inside diameter (DI)	20.1 mm
Total length (L)	1.5 mm
General information	
Delivery quantity	100

Release date: 2020-06-02 Date of issue: 2020-06-02 Filename: 312496\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com

USA: +1 330 486 0002  
pa-info@us.pepperl-fuchs.com

Germany: +49 621 776 2222  
pa-info@de.pepperl-fuchs.com



















Singapore: +65 6779 9091  
pa-info@sg.pepperl-fuchs.com

**PF** PEPPERL+FUCHS

**Technical Data**

Scope of delivery washer gasket

**Matching system components**

	<b>CG.AR.M20L.SS. C.16.K15</b>	
	<b>CG.AR.M20.SS.C.16.K15</b>	
	<b>CG.AR.M20L.BN. C.16.K15</b>	
	<b>CG.AR.M20.BN.C.16.K15</b>	
	<b>CG.CO.M20.BN.C.16.K15</b>	
	<b>CG.EM.M20.BN.C.18.K50</b>	
	<b>CG.EM.M20.SS.C.18.K50</b>	
	<b>CG.NA.M20.BN.C.16.K50</b>	
	<b>CG.NA.M20S.BN. C.16.K50</b>	
	<b>CG.NA.M20.SS.C.16.K50</b>	
	<b>CG.NA.M20S.SS. C.16.K50</b>	
	<b>AD.M20.M16.BN. C.15.K63</b>	
	<b>AD.M20.NPT1/2.BN. C.15.K35</b>	
	<b>AD.M20.NPT1/2.SS. C.15.K35</b>	
	<b>AD.M20.NPT3/4.BN. C.15.K35</b>	
	<b>AD.M20.NPT3/4.SS. C.15.K35</b>	
	<b>SP.MD.M20.BN.C.15.K50</b>	
	<b>SP.MD.M20.SS.C.15.K50</b>	

Release date: 2020-06-02 Date of issue: 2020-06-02 Filename: 312496\_eng.pdf