
 


Basic series
 15 mm embeddable
 increased operating
 distance

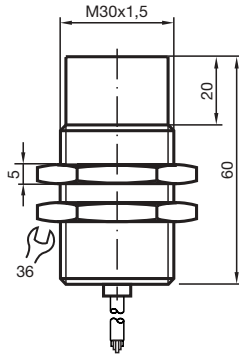

Switching element function	NPN	Make function
Rated operating distance s_n	15 mm	
Installation	embeddable	
Assured operating distance s_a	0 ... 12,15 mm	
Reduction factor r_{Al}	0,3	
Reduction factor r_{Cu}	0,3	
Reduction factor r_{V2A}	0,75	
Operating voltage U_B	10 ... 30 V	
Switching frequency f	0 ... 200 Hz	
Reverse polarity protection	Protected against reverse polarity	
Short circuit protection	pulsing	
Voltage drop U_d	Ω 3 V	
Operating current I_L	0 ... 200 mA	
Off-state current I_r	0 ... 0,5 mA typ.	
No-load supply current I_0	Ω 15 mA	
Indication of the switching state	all direction LED, yellow	
Standards	EN 60947-5-2	
Ambient temperature	-25 ... 70 °C (248 ... 343 K)	
Connection type	2 m, PVC cable	
Core cross-section	0.34 mm ²	
Housing material	brass, nickel-plated	
Sensing face	PBT	
Protection degree	IP67	

Connection_type:



450329_ENG.xml

2003-07-09