

Features


- Enables easy, centralized management of a Remote Monitor via the VisuNet Control Center

Application

Pepperl+Fuchs VisuNet Remote Monitors (VisuNet RMs) are industrial-grade thin client solutions that give users a simplified, modern user interface. The firmware of a VisuNet RM, called VisuNet RM Shell, enables users to easily access applications that run on process control systems via Ethernet.

With the CC license key, the “VisuNet Control Center interface” feature can be enabled in the RM Shell 5.x (or newer). This interface enables an RM to be centrally managed via the VisuNet Control Center. This allows functions such as downloading/uploading profiles, changing device settings, and session shadowing.

CC License

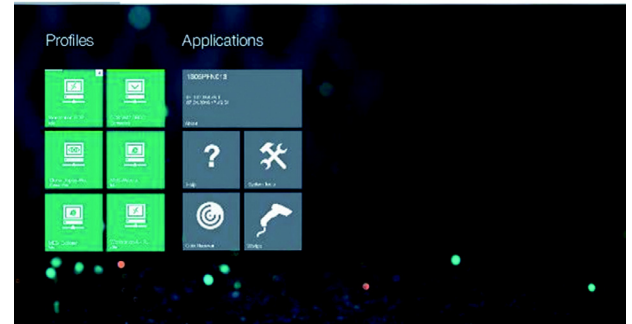

Software	
Operating system	based on Microsoft Windows 10 IoT Enterprise LTSB
Languages	English
Licensing	
Available licenses	1x license key to enable "Control Center interface" feature of one VisuNet Remote Monitor with pre-installed RM Shell 5.x (or newer)
Installation	Licenses can only be enabled in the RM Shell 5.x (or newer) by user role "Administrator".
Associated products	VisuNet Remote Monitors with pre-installed RM Shell 5.x VisuNet Control Center

License Bundles

Product	Number of Licenses	Part Number
VISUNET-RM-SHELL5-CC-5	5	548285
VISUNET-RM-SHELL5-CC-10	10	548286
VISUNET-RM-SHELL5-CC-30	30	548287
VISUNET-RM-SHELL5-CC-50	50	548288