

Y-Splitter

V3S-GR-YEE-V3/V3-GR




- Easy merging of two signals at a single M8 slot
- Snap locking
- Free of paint wetting interfering substances
- Degree of protection IP65
- UL listed for USA and Canada

Y-Splitter M8 plug snap-lock 3-pin to 2x M8 socket snap-lock 3-pin, UL approved



Dimensions

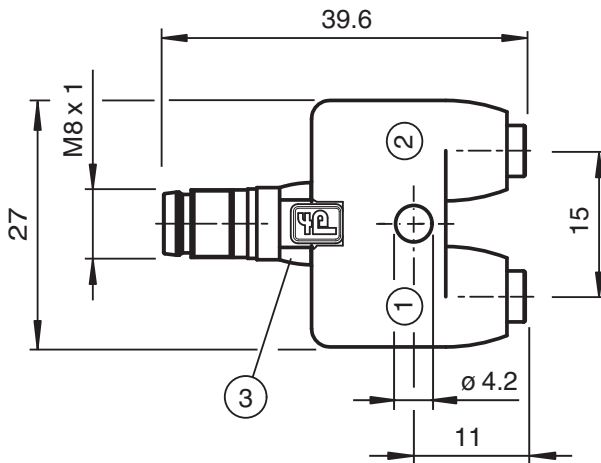

Technical Data

General specifications

Connector 1	
Connection	socket
Construction type	M8
Style	straight
Locking	snap locking
Number of pins	3
Coding	A-coded
Connector 2	
Connection	socket
Construction type	M8
Style	straight
Locking	snap locking
Number of pins	3
Coding	A-coded
Connector 3	
Connection	plug

Release date: 2024-03-15 Date of issue: 2024-03-15 Filename: 70101374_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com


Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

PF PEPPERL+FUCHS

Technical Data

Construction type		M8
Style		straight
Locking		snap locking
Number of pins		3
Coding		A-coded
Electrical specifications		
Operating voltage	U _B	max. 30 V AC/DC
Operating current	I _B	max. 3 A
Conformity		
Degree of protection		EN 60529
Plug connection		connector M8 x 1 : IEC 61076-2-104
Flammability		IEC 60332-1-2
Approvals and certificates		
UL File Number		E231213
Ambient conditions		
Ambient temperature		-40 ... 80 °C (-40 ... 176 °F)
Pollution degree		3
Mechanical specifications		
Plug connector		
Mating cycles		min. 100
Degree of protection		IP65
Material		
Plug connector		
Body		TPU, black
Contact surface		Au
Flammability		V-0

Connection Assignment

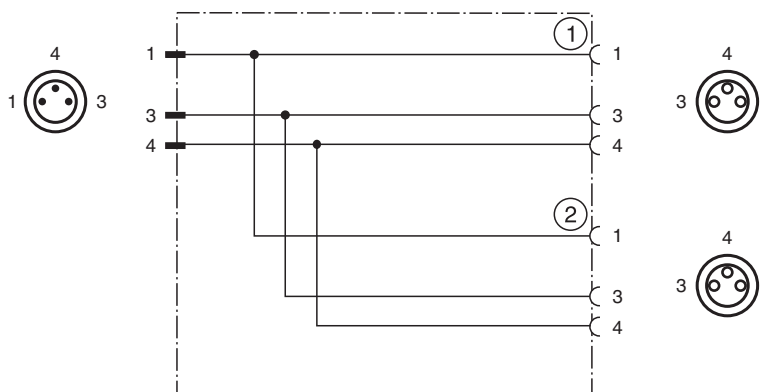

Release date: 2024-03-15 Date of issue: 2024-03-15 Filename: 70101374_eng.pdf