


Connection cable

V93-G-YE20M-STOOW-V93-G

■ Thread 7/8 inch

Connection cable, 7/8" to 7/8", STOOW cable 3-pin

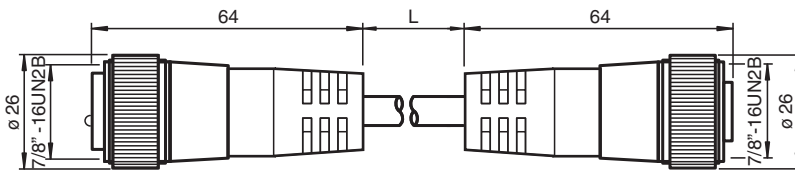

Technical Data

General specifications

Number of pins	3
Connection 1	socket
Construction type 1	straight
Threading 1	7/8 inch
Connection 2	Male connector
Construction type 2	straight
Threading 2	7/8 inch

Electrical specifications

Operating voltage	U_B	max. 600 V
Operating current	I_B	13 A
Volume resistance		< 5 m Ω

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------

Mechanical specifications

Degree of protection	IP67
Material	
Contacts	Cu alloy gold plated
Body	PVC, yellow
Cable	PVC
Slotted nut	nickel-plated brass
Core insulation	PVC

Release date: 2020-06-25 Date of issue: 2020-06-25 Filename: 70119780_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com



Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

PEPPERL+FUCHS

Technical Data

Cable		fine-strand, flexible
Sheath diameter		Ø 9.9 mm
Bending radius		10 x cable diameter
Color		yellow
Cores		3 x 1.5 mm ² (16 AWG)
Length	L	20 m
Note		STOOW UL Standard

Connection

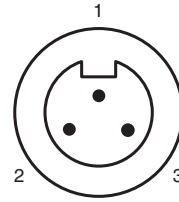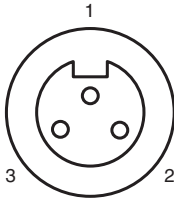

Release date: 2020-06-25 Date of issue: 2020-06-25 Filename: 70119780_eng.pdf