


Connection cable

V94-G-YE6M-STOOW-V94-G

■ Thread 7/8 inch

Connection cable, 7/8" to 7/8", STOOW cable 4-pin

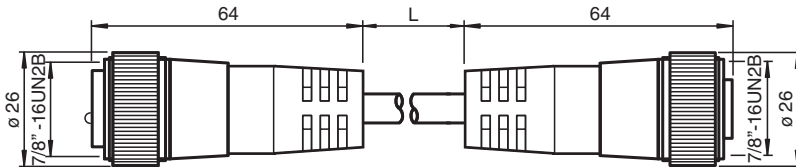

Technical Data

General specifications

Number of pins	4
Connection 1	socket
Construction type 1	straight
Threading 1	7/8 inch
Connection 2	plug
Construction type 2	straight
Threading 2	7/8 inch

Electrical specifications

Operating voltage	U_B	max. 600 V
Operating current	I_B	10 A
Volume resistance		< 5 m Ω

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------

Mechanical specifications

Degree of protection	IP67
Material	
Contacts	Cu alloy gold plated
Body	PVC, yellow
Cable	PVC
Slotted nut	nickel-plated brass
Core insulation	PVC
Cable	fine-strand, flexible

Release date: 2020-12-11 Date of issue: 2020-12-11 Filename: 70119789_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com


Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

PEPPERL+FUCHS

Technical Data

Sheath diameter	Ø 9.9 mm	
Bending radius	10 x cable diameter	
Color	yellow	
Cores	4 x 1.5 mm ² (16 AWG)	
Length	L	6 m
Note	STOOW UL Standard	

Connection

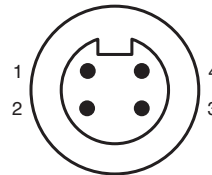

Release date: 2020-12-11 Date of issue: 2020-12-11 Filename: 70119789_eng.pdf