



Stack light LED permanent light element


VAZ-LED-38MM-YE-RD-2M

- Preconfigured stack light
- Long lifetime
- Two-color (yellow and red)
- 2 meter fixed cable

Stack light LED permanent light element, 2-stage signaling



Dimensions

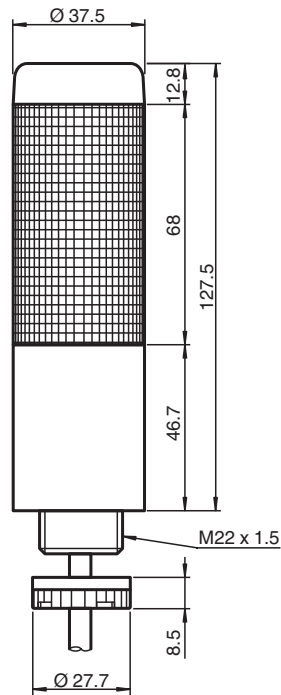

Technical Data

General specifications

Light type	LED solid
Color	yellow/red

Electrical specifications

Rated operating voltage	U_e	24 V AC/DC \pm 10 %
Rated operating current	I_e	60 mA
Supply frequency		50 Hz
Protection class		II
Inrush current		500 mA

Ambient conditions

Release date: 2020-12-09 Date of issue: 2021-01-04 Filename: 70127454_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

PEPPERL+FUCHS

Technical Data

Ambient temperature	-20 ... 50 °C (-4 ... 122 °F)
Pollution degree	3, in connection area 2
Mechanical specifications	
Housing height	141 mm
Degree of protection	IP65
Connection	cable
Cable entry	Membrane sleeve, max. core cross section 0.34 mm ² /AWG22
Material	PC
Mass	146 g
Cable length	2 m
Life span	max. 50,000 h