



# Drive-over profile rail PGV-PR-SM-CONT500

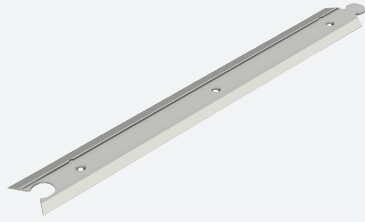

- Sturdy construction

Drive-over rail to realize endless tracks

## Dimensions

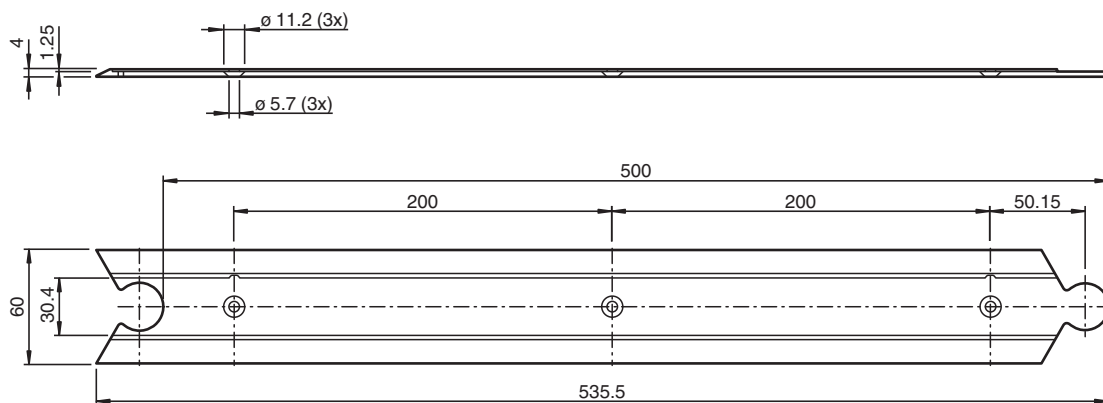

## Technical Data

### General specifications

Length	535.5 mm
Width	60 mm

### Ambient conditions

Operating temperature	-40 ... 80 °C (-40 ... 176 °F)
Installation temperature	10 ... 40 °C (50 ... 104 °F)



### Mechanical specifications

Material thickness	4 mm
Material	AlMg4.5Mn0.7
Surface	ELOX-E0EV1-15
Mass	209 g

## Mounting

Drive-over profile rails are screwed directly to the floor. Alternatively, the drive-over profile rails can be glued to the subfloor. The corresponding metal code bar is then inserted into the drive-over profile rails via the self-adhesive rear side. If necessary, metal code bars that have been glued in can be replaced by levering them out.

**Accessories**

	<b>PGV-PR-SM-END</b>	Drive-over rail to end continuous tracks
	<b>PGV-PR-SM-START</b>	Drive-over rail for starting continuous tracks