




Accessory camera lens VOS-LE-C-25MM-JC

- Exchangeable lens (C-Mount)
- Focal length 25 mm
- F 1.6-16
- Format 2/3"
- MOD 0.2 m
- C-mount

Fixed focal length lens, high-resolution, compact Megapixel lens, with locking screws for C-mount cameras

Dimensions

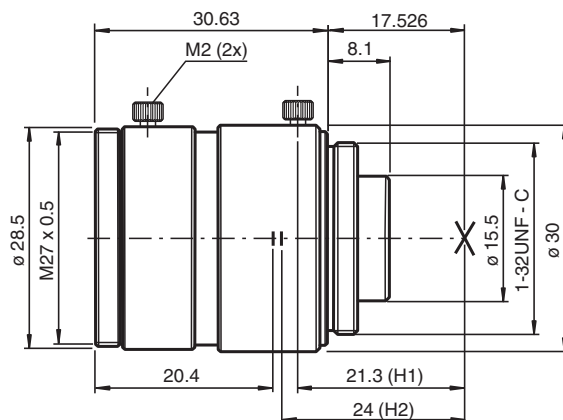

Technical Data

General specifications

Focal length	25 mm
Format	2/3"
Aperture	F1,6-16
Aperture contro	manually
Horizontal angle of view	21 °
Vertical angle of view	15.7 °
Diagonal angle of view	26.3 °
At image format	6.6 x 8.8 mm
MOD (Minimum object distance)	200 mm

Ambient conditions

Operating temperature	-10 ... 50 °C (14 ... 122 °F)
Storage temperature	-20 ... 60 °C (-4 ... 140 °F)

Mechanical specifications

Housing length	28 mm
Housing diameter	Ø 30 mm

Release date: 2021-08-27 Date of issue: 2021-08-27 Filename: 70142265_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com

PF PEPPERL+FUCHS

Technical Data

Mass	55 g
Objective connection	C-mount
Filter thread	M 27 × 0.5

Release date: 2021-08-27 Date of issue: 2021-08-27 Filename: 70142265_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group
www.pepperl-fuchs.com

USA: +1 330 486 0001
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091
fa-info@sg.pepperl-fuchs.com