




CE

### Model Number

**CBL SET J03M-BK-2m**

Connection cable

### Dimensions

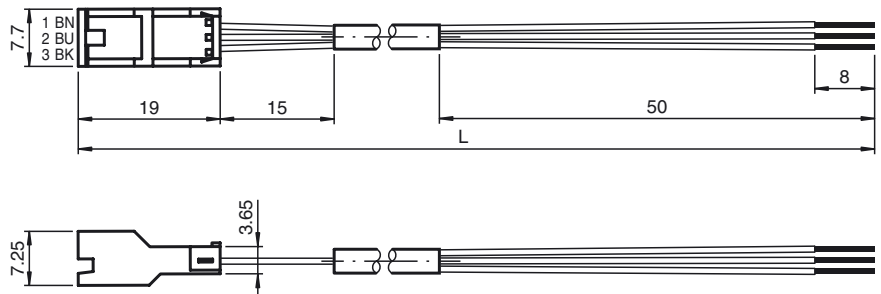

### Technical data

#### General specifications

Number of pins	3
Construction type	Socket, straight free cable end

#### Ambient conditions

Ambient temperature	-25 ... 70 °C (-13 ... 158 °F)
---------------------	--------------------------------

#### Mechanical specifications

Degree of protection	IP20
Connection	cable with 3-pin JST connector
Material	
Body	PA66
Cable	PVC
Cable	fine-strand, flexible
Sheath diameter	Ø 3 mm
Color	black
Cores	3 x 0.14 mm <sup>2</sup>
Conductor construction	18 x 0.1 mm
Length	L 2 m (L)
Mass	approx. 30 g

#### Electrical connection

1)	_____	BN
2)	_____	BU
3)	_____	BK