






**Model number**  
**VAZ-RK-4TEE**  
 AS-Interface four port passive splitter

- Features**
- Passive four port Tee for AS-Interface

**Dimensions**

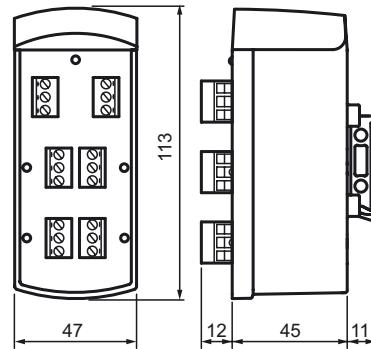

**Electrical connection**

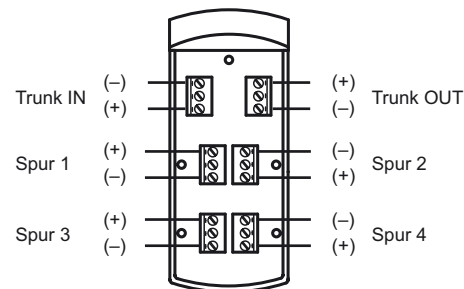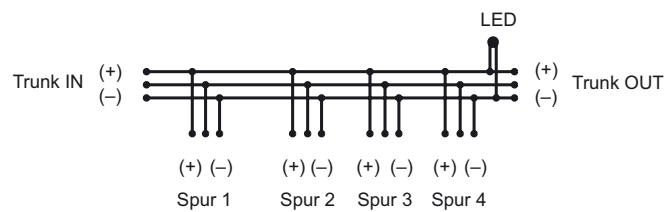

**Technical data**

<b>General specifications</b>	
Description	AS-Interface four port passive splitter
<b>Indicators/operating means</b>	
LED PWR	LED green: bus power
<b>Electrical specifications</b>	
Rated operating voltage	$U_e$ 26.5 ... 31.6 V from AS-Interface
Rated operating current	$I_e$ 8 A
Maximum safe voltage	$U_m$ 35 V
<b>Interface</b>	
Protocol	AS-Interface
<b>Output</b>	
Number/Type	4/drop connectors
<b>Ambient conditions</b>	
Ambient temperature	-40 ... 85 °C (-40 ... 185 °F)
Storage temperature	-40 ... 85 °C (-40 ... 185 °F)
<b>Mechanical specifications</b>	
Protection degree	IP20
Connection	terminals: trunk in, trunk out and 4 drops

Release date: 2010-03-30 20:11 Date of issue: 2014-01-13 905374\_eng.xml

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
 www.pepperl-fuchs.com

USA: +1 330 486 0001  
 fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 4411  
 fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091  
 fa-info@sg.pepperl-fuchs.com