




Model Number

1/2" NPT-V95-G-S-.3M

Male receptacle, 7/8" UN / 1/2" NPT, 5-pin

Dimensions

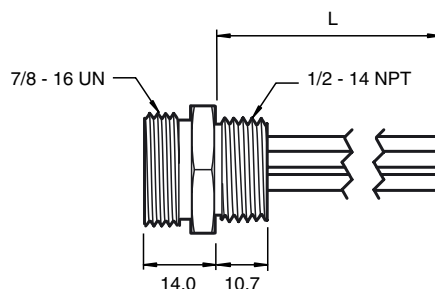

Technical data

General specifications

Number of pins	5
Construction type	straight
Connection 1	Male connector
Threading 1	7/8"

Electrical specifications

Operating voltage	U_B	max 600 V AC/DC
Operating current		8 A

Ambient conditions

Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------


Mechanical specifications

Protection degree	IP67
Connection	7/8"-16 UN connector
Material	clear anodized aluminum
Contacts	gold plated copper alloy
Cable	
Cores	5 x 1.5 mm ²
Length	L 0.3 m
Note	1/2" - 14 NPT installation thread

Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

Electrical connection

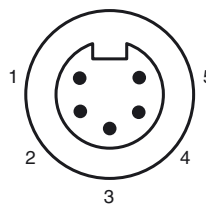

Electrical connection

1	—————	WH
2	·····	RD
3	—————	GN/YE
4	·····	OR
5	—————	BK