



### Model Number


**V95-G-SE**

Male connector, 7/8" - 16 UN2A, 5-pin, field attachable

### Features

- Screw terminal connection
- External connector thread
- Gold plated contacts

## Dimensions

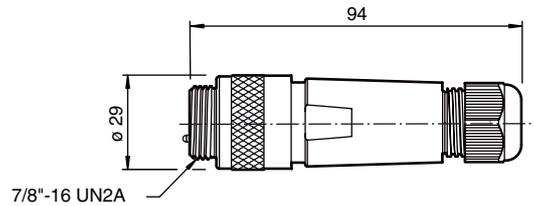

## Technical data

### General specifications

Number of pins	5
Connection 1	Male connector
Construction type 1	straight
Threading 1	7/8"

### Electrical specifications

Operating voltage	$U_B$	max. 600 V
Operating current		12 A max
Volume resistance		$\leq 5 \text{ m}\Omega$

### Ambient conditions

Ambient temperature	-40 ... 90 °C (-40 ... 194 °F)
---------------------	--------------------------------

### Mechanical specifications

Degree of protection	IP67
Connection	1 x 7/8"-16 UN - 2A ; Connector, straight screw terminal for 14 - 22 AWG

#### Material

Contacts	gold plated Cu alloy
Body	Polyamide (PA)
Slotted nut	black anodized aluminum
Sleeve connector	yellow PVC

#### Cable

Sheath diameter	5 ... 13 mm
-----------------	-------------

### Approvals and certificates

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

## Electrical connection

