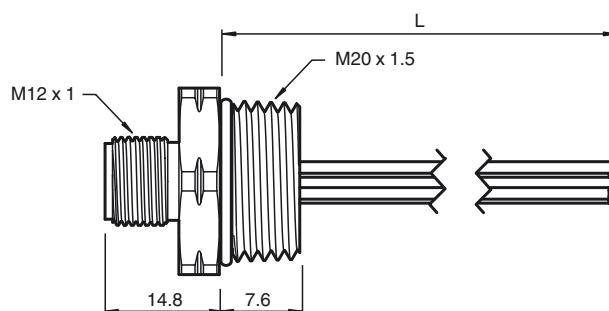


**Model Number****M20-V1-G-S-.3M**

Male receptacle

**Dimensions****Technical data****General specifications**

Number of pins	4
Construction type	straight

**Electrical specifications**

Operating voltage	$U_B$	max. 300 V AC/DC
Operating current	$I_B$	max. 4 A

**Ambient conditions**


Ambient temperature	-40 ... 105 °C (-40 ... 221 °F)
---------------------	---------------------------------

**Mechanical specifications**

Degree of protection	IP67
Connection	Single strand leads
Material	anodized aluminum
Contacts	Gold plated copper alloy
Sleeve connector	Polyamide (PA)
Seal	NBR
Cable	
Cores	4 x 0.34 mm <sup>2</sup> , 22 AWG
Length	L 0.3 m
Note	M20 x 1.5 installation

**Approvals and certificates**

UL approval	cULus Listed, General Purpose
-------------	-------------------------------

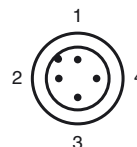**Electrical connection****Electrical connection**

1	BN
2	WH
3	BU
4	BK