




Dimensions

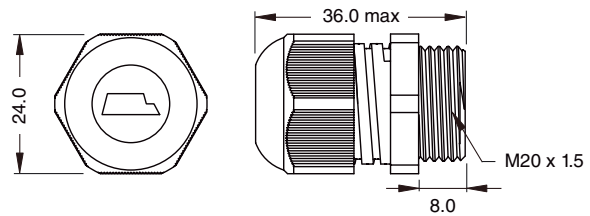

Model number

VAZ-FK-GLAND-M20

Flat cable sleeve

Features

- IP65 rugged industrial housing
- Cord grip for connection of 1 AS-Interface flat cable
- Mounting nuts included with delivery

Note

M20 cable gland

Technical data

Ambient conditions

Ambient temperature -20 ... 100 °C (-4 ... 212 °F)

Mechanical specifications

Degree of protection	IP65
Connection	1 Flat cable
Material	PA 6 V-2 Neoprene
Installation	M20 cable gland No O-Ring necessary to obtain IP65 seal. Crush ribs on underside of HEX will provide the seal