

## Accessory photo

### OMH-VDM28-CID1




- Explosion-proof housing
- Approved for Class I, Groups C, D
- Approved for Class II, Groups E, F and G
- Internal terminal block and 4-pin M12 plug angled

Protective enclosure



## Dimensions

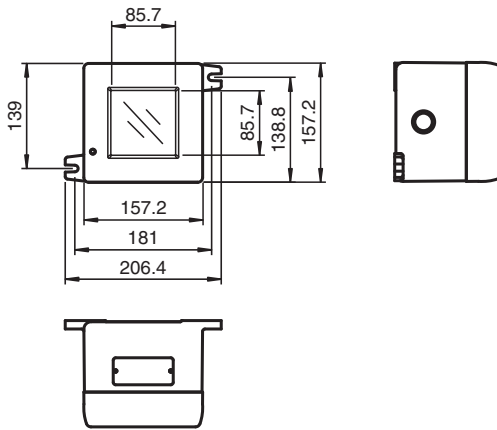

## Technical Data

General specifications	
Accessories provided	
Approvals and certificates	
UL approval	Class I, Division 1, Groups C, D
Ambient conditions	
Ambient temperature	-25 ... 70 °C (-13 ... 158 °F)
Storage temperature	-40 ... 85 °C (-40 ... 185 °F)
Mechanical specifications	
Housing width	157 mm
Housing height	140 mm
Degree of protection	NEMA Type 4, 7, 9
Connection	Terminals
Material	
Housing	diecast aluminum
Mass	approx. 5896 g

Release date: 2023-03-20 Date of issue: 2023-03-20 Filename: 915641\_eng.pdf

Refer to "General Notes Relating to Pepperl+Fuchs Product Information".

Pepperl+Fuchs Group  
www.pepperl-fuchs.com


USA: +1 330 486 0001  
fa-info@us.pepperl-fuchs.com

Germany: +49 621 776 1111  
fa-info@de.pepperl-fuchs.com

Singapore: +65 6779 9091  
fa-info@sg.pepperl-fuchs.com

PEPPERL+FUCHS

## Connection Assignment

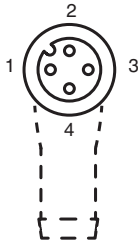

1	BN
2	WH
3	BU
4	BK